




Pushing Performance

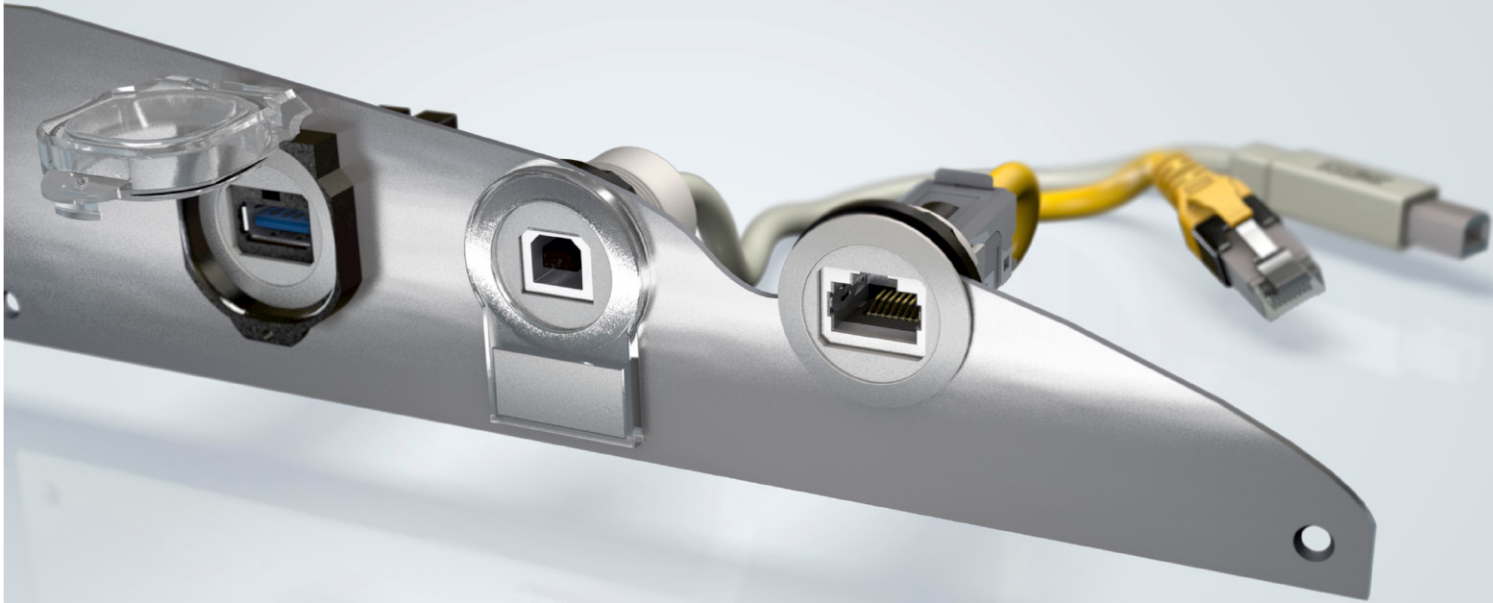

People | Power | Partnership

HARTING Selection Guide

har-port Service Interfaces

HARTING Selection Guide

har-port service interfaces


HARTING's *har-port* offers a sophisticated and visually appealing system for service interfaces to industrial machinery, switch cabinets, medical and building services technology.

In addition to time-saving installation with pre-connected patch cables, the wide range of accessories is particularly impressive: from snap-on label holders to protective covers in IP65 / IP67.

har-port

Easy access for service personnel.




Practical accessories (protective covers in IP65 / IP67 and label holders that can be snapped on retroactively)

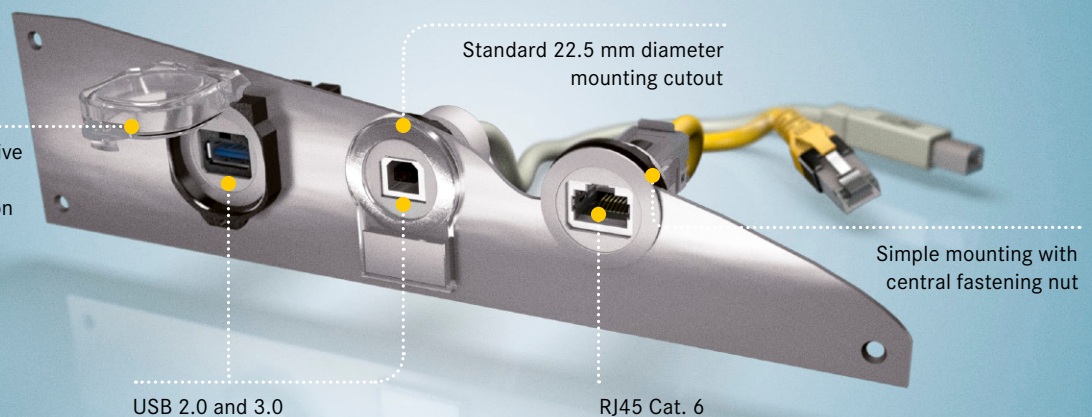



 
People | Power | Partnership

- Usable for Ethernet 1/10 Gbit or USB 2.0 / 3.0
- Simple mounting with the M22 central fastening
- Practical accessories

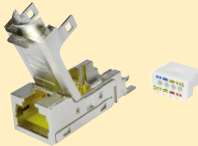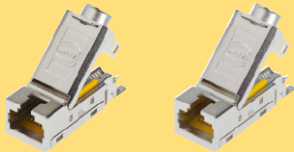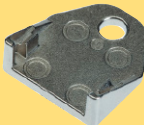

	Pictures	Characteristics		Part number	
har-port RJ45 Ethernet Interfaces		Ethernet interface RJ45 jack – RJ45 jack	har-port RJ45 Cat. 6 service interface	silver 09 45 452 1560	black 09 45 452 1561
		Ethernet interface RJ45 jack – RJ45 connector	har-port RJ45 Cat. 6 _A service interface Length: 0.15 m 0.2 m 0.3 m 0.4 m 0.5 m 0.6 m 0.7 m 0.8 m 0.9 m 1.0 m 1.5 m 2.0 m 2.5 m 3.0 m 3.5 m 4.0 m 5.0 m 7.5 m 10.0 m	silver 09 45 452 1500 09 45 452 1501 09 45 452 1502 09 45 452 1503 09 45 452 1504 09 45 452 1505 09 45 452 1506 09 45 452 1507 09 45 452 1508 09 45 452 1509 09 45 452 1510 09 45 452 1511 09 45 452 1512 09 45 452 1513 09 45 452 1514 09 45 452 1515 09 45 452 1516 09 45 452 1517 09 45 452 1518	black 09 45 452 1530 09 45 452 1531 09 45 452 1532 09 45 452 1533 09 45 452 1534 09 45 452 1535 09 45 452 1536 09 45 452 1537 09 45 452 1538 09 45 452 1539 09 45 452 1540 09 45 452 1541 09 45 452 1542 09 45 452 1543 09 45 452 1544 09 45 452 1545 09 45 452 1546 09 45 452 1547 09 45 452 1548
		Coupler housing to build up customer specific Ethernet interfaces	har-port coupler housing (for all HIFF compatible modules)	silver 09 45 452 0000	black 09 45 452 0001
		RJ45 cable jacks with IDC termination	HARTING RJ45 HIFF cable jack, Cat. 5, AWG 24-22, 4 poles	09 45 545 1120	
			HARTING RJ45 HIFF cable jack, Cat. 6 _A , AWG 28-24, 8 poles	09 45 545 1561	
			HARTING RJ45 HIFF cable jack, Cat. 6 _A , AWG 24-22, 8 poles	09 45 545 1562	
		RJ45 cable jacks with preLink® IDC termination	Ha-VIS preLink® RJ45 HIFF jack, Cat. 6 _A incl. cable termination AWG 23-22	20 82 001 0001	
			Ha-VIS preLink® RJ45 HIFF jack, Cat. 6 _A without cable termination	20 82 000 0002	
			Ha-VIS preLink® terminal module AWG 23-22	20 82 000 0001	
			Ha-VIS preLink® terminal module AWG 27-26	20 82 000 0003	
			Ha-VIS preLink® assembly tool	20 82 000 9901	
			Unlocking tool to open RJ45 jack modules	20 82 000 9916	

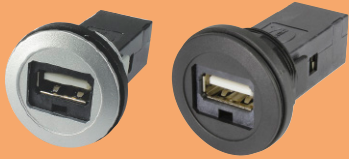	Pictures	Characteristics		Part number	
har-port USB-Interfaces		USB – Interface type A jack – type A jack	har-port USB 2.0 A-A service interface	silver 09 45 452 1901	black 09 45 452 1903
			har-port USB 3.0 A-A service interface	09 45 452 1902	09 45 452 1904
		USB 2.0 – Interface type A jack – type A connector	har-port USB 2.0 A-A service interface Length:	silver 09 45 452 1927	black 09 45 452 1960
			0.15 m 0.4 m 0.5 m 1.0 m 1.5 m 2.0 m 3.0 m 4.0 m 5.0 m	09 45 452 1928 09 45 452 1920 09 45 452 1921 09 45 452 1922 09 45 452 1923 09 45 452 1924 09 45 452 1926 09 45 452 1925	09 45 452 1961 09 45 452 1962 09 45 452 1963 09 45 452 1964 09 45 452 1965
		USB 2.0 – Interface 2x type A jack – 2x type A connector	har-port USB 2.0 A-A service interface silver Length:	09 45 452 1950 09 45 452 1951 09 45 452 1952 09 45 452 1953 09 45 452 1954 09 45 452 1955	
		USB 2.0 – Interface type B jack – type B connector	har-port USB 2.0 B-B service interface silver Length:	09 45 452 1910 09 45 452 1911 09 45 452 1912 09 45 452 1913 09 45 452 1914 09 45 452 1916 09 45 452 1915	
		USB 3.0 – Interface type A jack – type A connector	har-port USB 3.0 A-A service interface Length:	silver 09 45 452 1930	black 09 45 452 1970
			0.5 m 1.0 m 1.5 m 2.0 m 3.0 m	09 45 452 1931 09 45 452 1932 09 45 452 1933 09 45 452 1934	09 45 452 1971 09 45 452 1972 09 45 452 1973 09 45 452 1974
		USB 2.0 – Interface type mini-B jack – type A connector	har-port USB 2.0 Mini-B-A service interface silver Length:	09 45 452 1940	

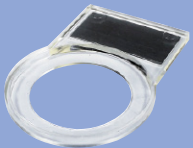	Pictures	Characteristics		Part number
<i>har-port</i> audio and video Interfaces		Audio interface 3.5 mm stereo phone jack, jack to connector	<i>har-port</i> audio interface phone jack 3.5 mm, silver Length: 1.0 m	09 45 452 1000
			<i>har-port</i> audio interface phone jack 3.5 mm, silver Length: 2.0 m	09 45 452 1001
		HDMI video interface	<i>har-port</i> video interface HDMI service interface, silver	09 45 452 1010
<i>har-port</i> Accessories		Dust and water protection in IP65 / IP67	<i>har-port</i> protection cover IP65 / IP67, black	09 45 502 0000
		Protects the <i>har-port</i> interfaces against unauthorised use	<i>har-port</i> sealing cover	09 45 502 0001
		Can be mounted later on	<i>har-port</i> label holder	09 45 502 0002
		Self-adhesive and inscribable	<i>har-port</i> label for <i>har-port</i> label holder 09 45 502 0002	09 45 502 0003
		To close unused <i>har-port</i> wall breaks	<i>har-port</i> blind cover IP65 / IP67	09 45 502 0004
		Dust and water protection in IP65 / IP67 Robust and sealable	<i>har-port</i> protection cover IP65 / IP67 transparent	09 45 502 0005
			black	09 45 502 0008
		Dust and water protection in IP65 / IP67 / IPx9k Very robust	<i>har-port</i> protection cover IP65 / IP67 / IPx9k metal	09 45 502 0006



Pushing Performance

HARTING.com –
the gateway to your country website.

www.HARTING.ae
www.HARTING.at
www.HARTING.com.au
www.HARTING.be
www.HARTING.com.br
www.HARTING.ca
www.HARTING.ch
www.HARTING.com.cn
www.HARTING.cz
www.HARTING.de
www.HARTING.dk
www.HARTING.es
www.HARTING.fi
www.HARTING.fr
www.HARTING.co.uk
www.HARTING.com.hk
www.HARTING.hu
www.HARTING.co.in
www.HARTING.it
www.HARTING.co.jp
www.HARTING.co.kr
www.HARTINGbv.nl
www.HARTING.no
www.HARTING.pl
www.HARTING.pt
www.HARTING.ro
www.HARTING.ru
www.HARTING.se
www.HARTING.sg
www.HARTING.sk
www.HARTING.com.tr
www.HARTING.com.tw
www.HARTING-USA.com
www.HARTING.co.za

HARTING Technology Group

info@HARTING.com

www.HARTING.com