



Vikuiti™ Advanced Light Control Film (ALCF-P)



Unique 3M technology helps protect proprietary corporate information and ensures compliance with current privacy legislation.

People and organizations all over the world are becoming more and more conscious about information security. And new laws are making it mandatory that companies take steps to keep confidential information secure. Display screens from computers and other devices are an often-overlooked source of security leaks. In fact, unprotected display screens can seriously compromise security by allowing unauthorized viewers access to otherwise protected information. Vikuiti™ Advanced Light Control Film is a simple, highly effective way to help protect the security of your display screens and those who use them.


Composed of invisible microlouvers that function like vertical blinds, Vikuiti advanced light control film blocks out display screen views from the side while allowing unrestricted viewing to users in front. Seen from the right or left, the screen appears dark; seen from the front, the screen is bright and clear. In fact, because the film blocks out light from the side, the image can be clearer and easier to read. So whether your customers are entering PIN numbers, studying financial records, working with sensitive documents or writing the next great screenplay, they can do so with confidence.

Vikuiti™ Advanced Light Control Film (ALCF-P)

3M Stock Number	Product Description	Abrasion Resistance	Viewing Angle	Surface Finish	Thickness	Size	Sheets/Kit
98-0440-4244-2	ALCF-P	None	60 degree	Gloss	0.021"	17" x 17"	10
98-0440-4264-0	ALCF-P	None	60 degree	Gloss	0.021"	12" x 11.5"	10
98-0440-4265-7	ALCF-P	None	60 degree	Gloss	0.021"	15" x 12"	10
98-0440-4242-6	ALCF-P	2-sided	60 degree	Matte	0.021"	17" x 17"	10
98-0440-4266-5	ALCF-P	2-sided	60 degree	Matte	0.021"	12" x 11.5"	10
98-0440-4267-3	ALCF-P	2-sided	60 degree	Matte	0.021"	15" x 12"	10



Specifications

Property	ALCF-P	LCF-P
Louver Angle	60°±4°	0°±8°
View Angle	0°±2°	60°±8°
Thickness	.021"±.003"	.032"±.005"
Visual Appearance (Particles/Bubbles/ Lint/Tooling)	>0.025": none allowed Up to .025": 3 per part, minimum space 2" <.010": Disregard if not visible at 18" to 24" unless clustered in 0.125" diameter area	>0.025": none allowed Up to .025": 3 per part, minimum space 2" <.010": Disregard if not visible at 18" to 24" unless clustered in 0.125" diameter area

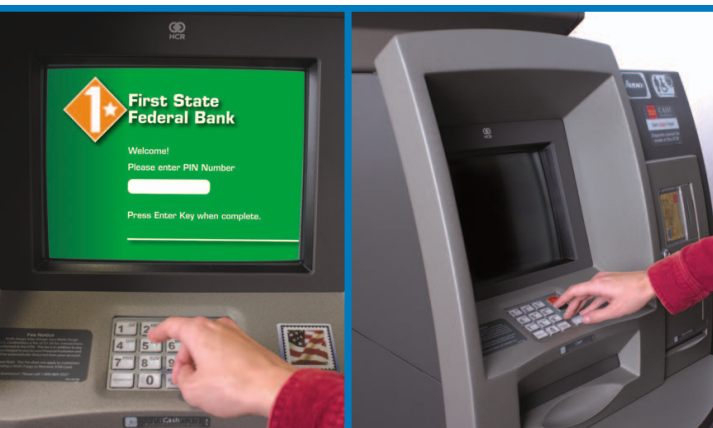

What users see.

What onlookers see.

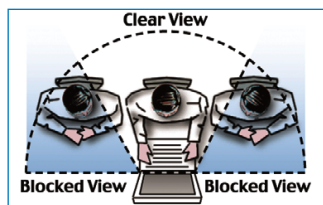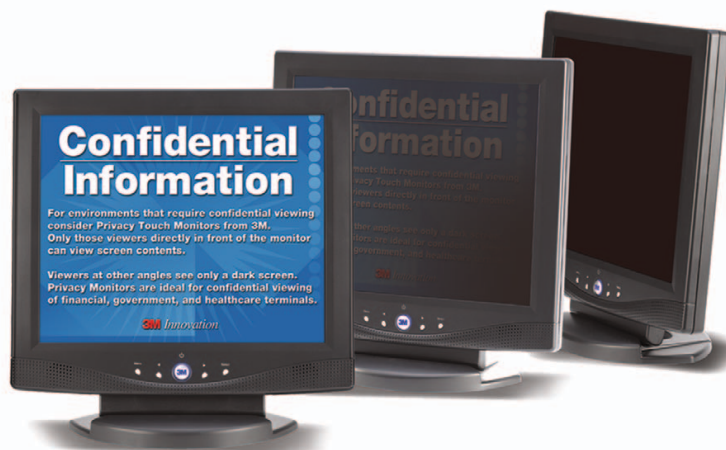

For ordering information on Vikuiti™ Display Enhancement Films from 3M, please call: **1-800-553-9215**

For more information, visit us at:
www.3M.com/Vikuiti

Important Notice to Purchaser

The following is made in lieu of all warranties, express or implied, including any implied warranties of merchantability or fitness for a particular purpose.

3M warrants that, at the time of shipment, product will meet 3M's published specification or that specification agreed in writing between 3M and purchaser.

Should product not meet specifications at time of shipment, 3M will replace or refund the purchase price of such quantity of the

product found not to meet specifications. Purchaser shall determine the suitability of the 3M product for purchaser's application. 3M shall not be liable under any legal theory, including in contract or in tort, for any injury, loss, or damage, whether direct, indirect, incidental, special or consequential, arising out of the use of or the inability to use the product.

The warranties and remedies set forth herein are purchaser's sole and exclusive warranties and remedies.



Optical Systems Division

3M Center, Building 275-6E-07
St. Paul, MN 55144-1000

Minimum 10% Post-Consumer Fiber

Vikuiti and the Vikuiti "Eye" symbol are trademarks of 3M.
Printed in U.S.A.
© 3M 2006
75-0500-5257-2