 
 
 
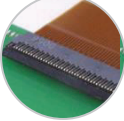
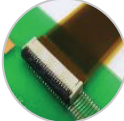
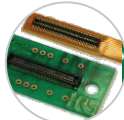
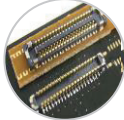
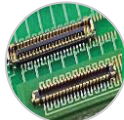
 
 
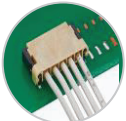




Web Camera | Thermostat | Voice Command Controller | Smart Detector | Smart Lock

HRS Products for Smart Home



Display | Camera | Speaker | Microphone | Sensor Connection

FPC/FFC Connector			Pitch (mm)	Stacking Height (mm)	Depth (mm)	Pin Count	Max. Rated Current (A)	
			TF38	0.5	5.20	4.96	18 to 60	0.5
			FH40 (Vertical)	0.5	5.80	3.55	10 to 80	0.5
			FH52	0.5/1.0	2.00	5.70	6 to 60	0.5
			FH34SRJ	0.5	1.0	3.80	4 to 50	0.5
			FH35C	0.3	0.9	4.20	9 to 61	0.2
			FH58/FH58M	0.2/0.25	0.9	3.10	7 to 71	0.2
Board to Board Connector			Pitch (mm)	Stacking Height (mm)	Depth (mm)	Pin Count	Max. Rated Current (A)	
			DF17	0.5	4.0 ~ 8.0	5.70	20 ~ 80	0.3
			DF12	0.5	3.0, 3.5, 4.0, 5.0	4.60	10 ~ 80	0.3
			DF40	0.4	1.5 ~ 4.0	3.38	10 ~ 100	0.3
			BM20	0.4	0.6 ,0.8	2.3	10 to 60	0.3
			BM23FR	0.35	0.6, 0.8	1.98	6 to 60	0.3
			BM28	0.35	0.6	1.7	6 to 60	4(Power), 0.3(Signal)
Board to Wire Connector			Pitch (mm)	Stacking Height (mm)	Depth (mm)	Pin Count	Max. Rated Current (A)	
			DF50A (Positive Lock)	1.0 Single-row	Vertical : 7.35 Horizontal : 7.05	Vertical : 6.85 Horizontal : 7.90	2 to 16	1.0
			DF20	1.0 Double -rows	Vertical : 5.80 Horizontal : 5.50	Vertical : 5.40 Horizontal : 6.20	10 to 50	1.0
			DF13 (SMT Type)	1.25 Single-row	Vertical : 5.80 Horizontal : 3.60	Vertical : 3.40 Horizontal : 6.00	2 to 15	1.0
			DF65 (Positive Lock)	1.7	Vertical : 1.80	6.30	3 to 7	4.0
			DF52	0.8	Horizontal : 1.75	4.10	2 to 20	2.5
			DF57H (Swing Lock)	1.2	Vertical : 1.40	4.65	2 to 6	2.5

Antenna Connection





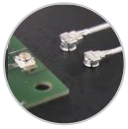
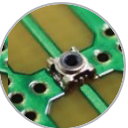
Micro Coaxial Connector		Frequency (GHz)	Occupied Mounting Area (mm)	Max. Stacking Height (mm)
 U.FL (A)  X.FL	U.FL (A)	DC to 6	3.0 x 3.1	2.0, 2.5
	X.FL	DC to 6 DC to 12 (Low Loss)	2.0 x 2.0	1.0 1.3 (Low Loss)
Micro Coaxial Switch		Frequency (GHz)	Occupied Mounting Area (mm)	Max. Stacking Height (mm)
 MS-156C3  MS-180  MS-190	MS-156C3	DC to 11	2.3 x 2.3	1.35
	MS-180	DC to 11	1.8 x 1.8	0.85
	MS-190	DC to 11	1.45 x 1.45	0.68

I/O Connection

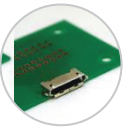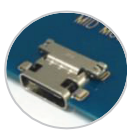I/O Connector			
 ZX Micro USB2.0	 ZX360 Micro USB3.0	 GX 0.4 mm pitch Compact I/F Connector	 CX70M USB Type C



Battery Connection

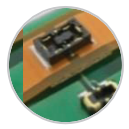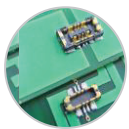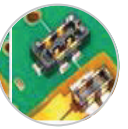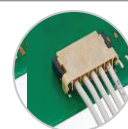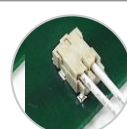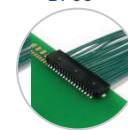Board to Board Connector		Pitch (mm)	Stacking Height (mm)	Depth (mm)	Pin Count	Max. Rated Current (A)
 BM22  BM25  KN14	BM22	0.4	0.9	2.64	2+2, 4+2	4A(Power), 0.3A(Signal)
	BM25	0.4	0.7	2.6	4+2, 6+2	9A(Power), 1A(Signal)
	KN14	-	0.7	2.2	2+2	6A(Power), 0.6A(Signal)
Board to Wire Connector		Pitch (mm)	Stacking Height (mm)	Depth (mm)	Pin Count	Max. Rated Current (A)
 DF65  DF61Y  DF52  DF57H	DF65 (Positive Lock)	1.7	Vertical : 1.80	6.30	3 to 7	4.0
	DF61Y (ViSe Lock)	2.2	Vertical : 2.00	7.35	2	2.0
	DF52	0.8	Horizontal : 1.75	4.10	2 to 20	2.5
	DF57H (Swing Lock)	1.2	Vertical : 1.40	4.65	2 to 6	2.5

For more information about Hirose products:

JAPAN CHINA HONG KONG TAIWAN KOREA SINGAPORE INDIA MALAYSIA THAILAND USA		TEL: 81-(0)45-620-3256 TEL: 86-21-6391-3355 TEL: 86-10-5165-9332 TEL: 86-755-8207-0851 TEL: 852-2803-5338 TEL: 886-2-2555-7377 TEL: 82-31-496-7000, 7124 TEL: 65-6324-6113 TEL: 91-12-660-8018 TEL: 91-80-4120-1907 TEL: 604-619-2564 TEL: 66-2-686-1255 TEL: 1-408-253-9640 TEL: 1-630-282-6701 TEL: 1-734-542-9963	EUROPE (The Netherlands) (Stuttgart) (Nuremberg) (Hanover) (Paris) (UK) (Finland)	TEL: 31-20-6557460 TEL: 49-711-4560-02-1 TEL: 49-911 32 68 89 63 TEL: 49-511 97 82 61 30 TEL: 33 (0) 1 7082 3170 TEL: 44-1908-202050 TEL: 358-50 432 8131
	(Shanghai) (Beijing) (Shenzhen) (Delhi) (Bangalore) (San Jose) (Chicago) (Detroit) (Automotive)			

<https://www.hirose.com/>



Specifications herein are subject to change without notice. Contact Hirose for latest specifications, drawings, or availabilities.